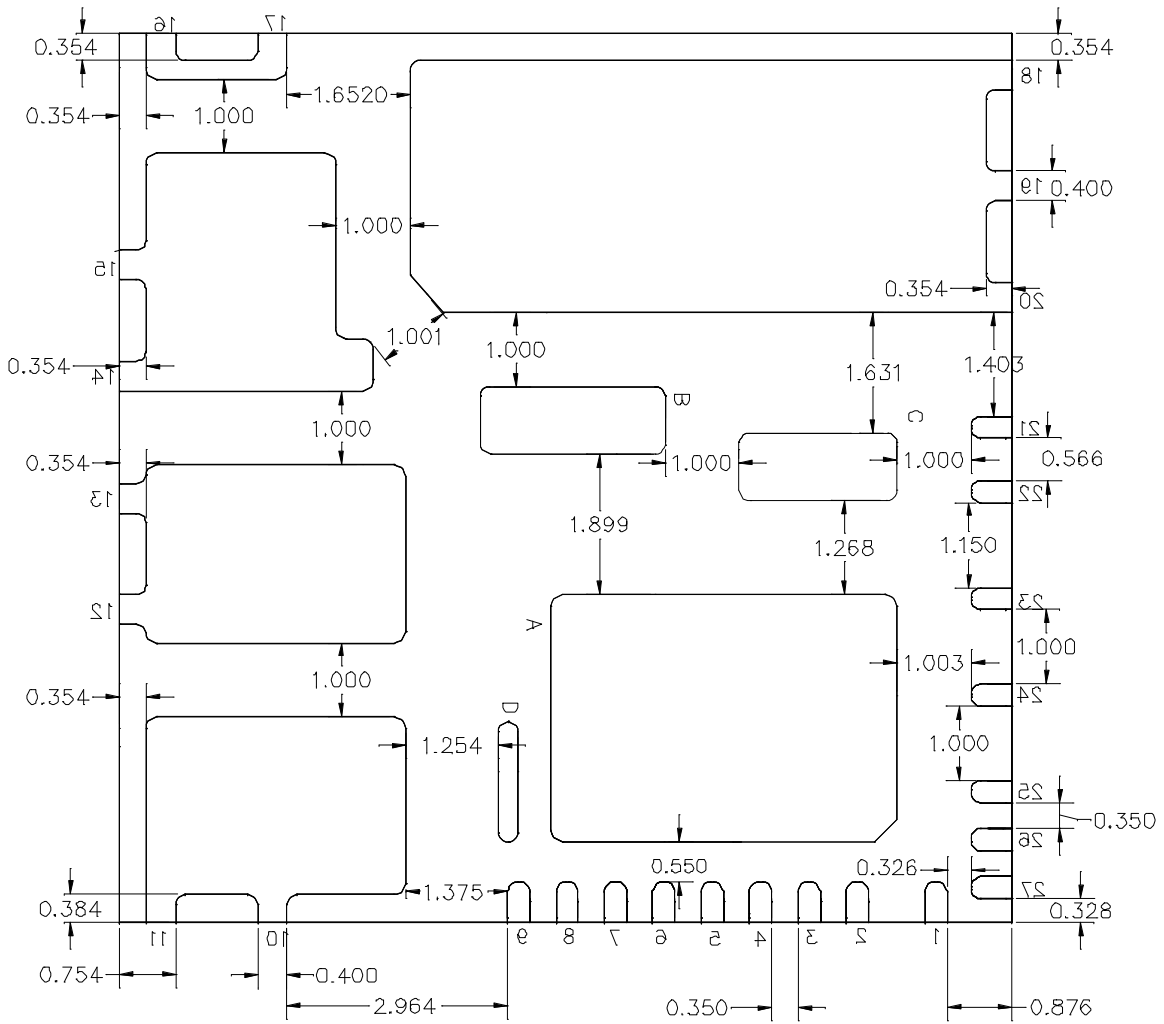
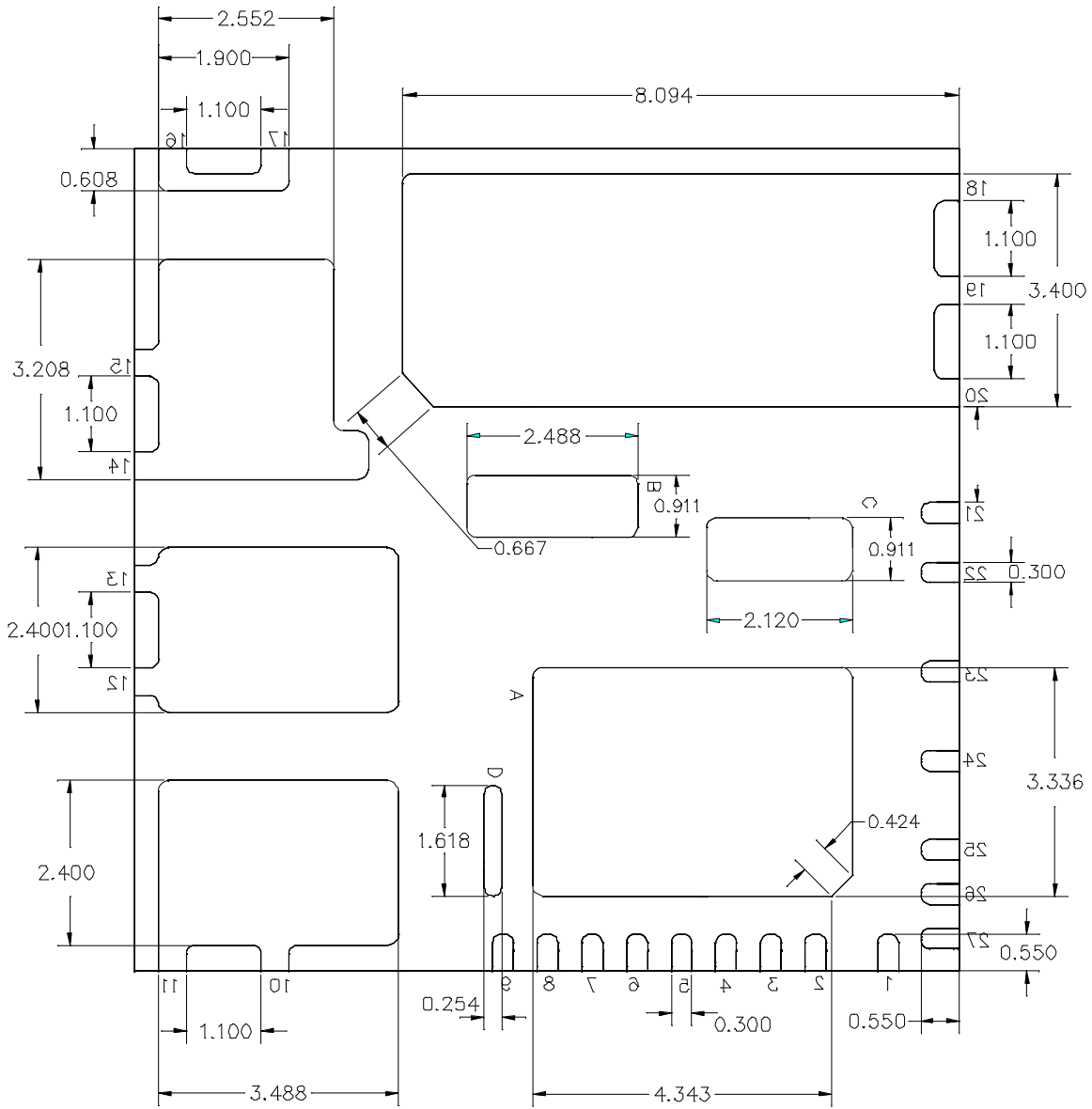
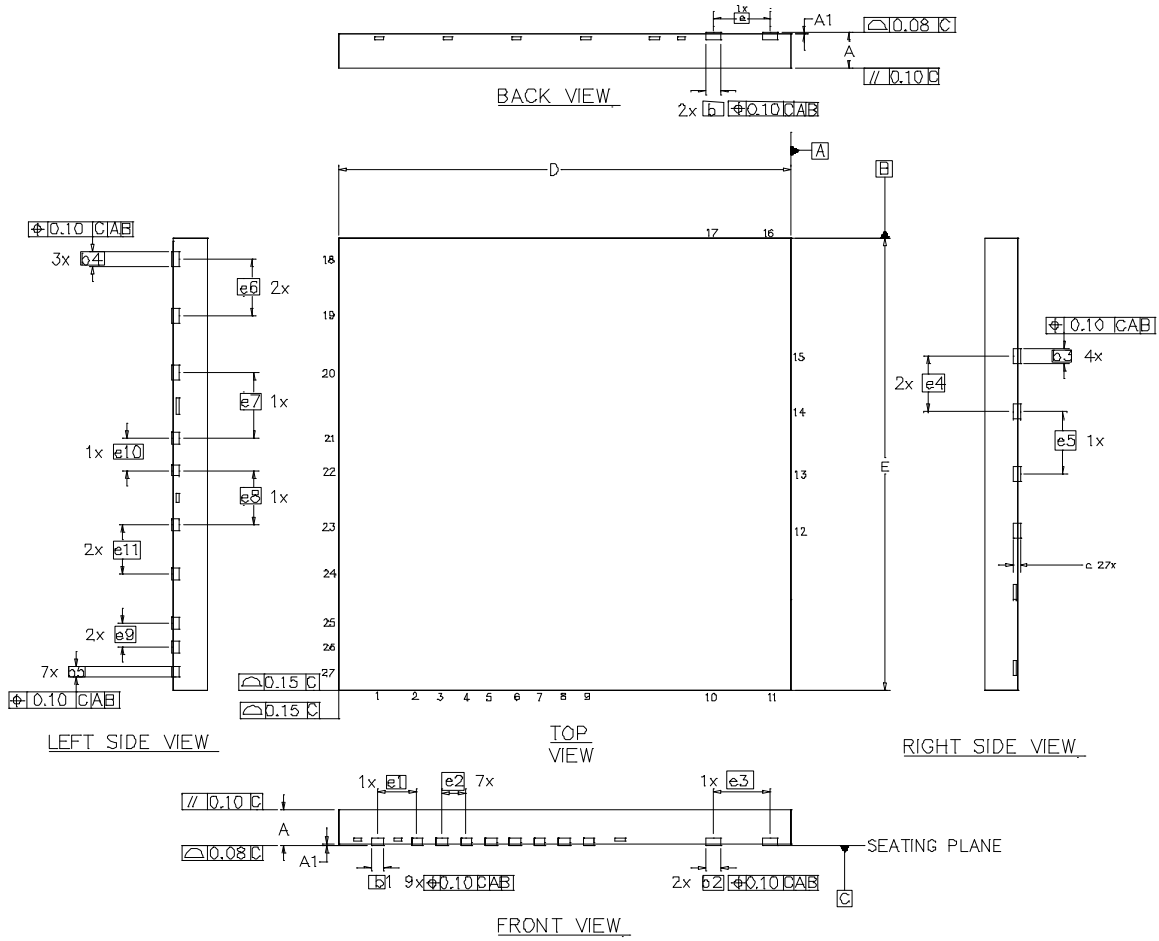


27L Package Outline IRSM836-035MB (Bottom View)


Dimensions in mm

27L Package Outline IRSM836-035MB (Bottom View)


Dimensions in mm

27L Package Outline IRSM836-035MB (Top and Side View)


DIM	MILLIMETERS		
	MIN	MAX	
A	0.800	1.000	
A1	0.000	0.050	
b	0.350	0.450	
b1	0.250	0.350	
b2	0.250	0.350	
b3	0.350	0.450	
b4	0.350	0.450	
b5	0.250	0.350	
c	0.203	REF.	
D	12.000	BASIC	
E	12.000	BASIC	
e	1.500	BASIC	
e1	1.056	BASIC	
e2	0.650	BASIC	
e3	1.500	BASIC	
e4	1.500	BASIC	
e5	1.650	BASIC	
e6	1.500	BASIC	
e7	1.753	BASIC	
e8	1.450	BASIC	
e9	0.650	BASIC	
e10	0.866	BASIC	
e11	1.300	BASIC	