
 
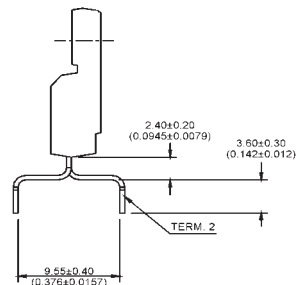
 




TO-220 FullPak Leadform Options

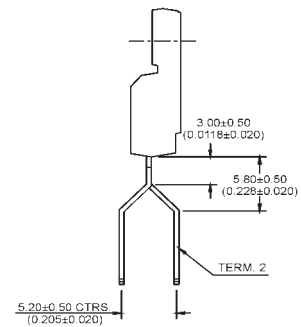



Option - 101




 
Option - 102

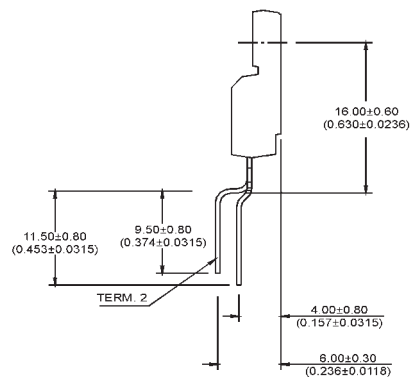



Option - 103

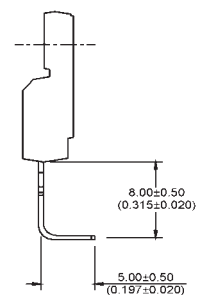 

Option - 104

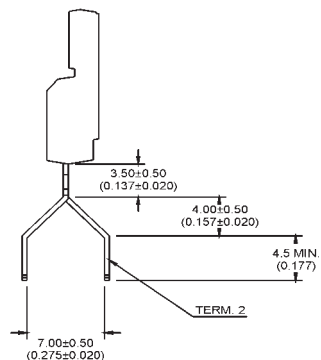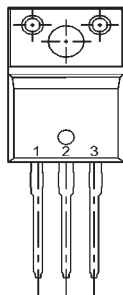

Option - 105

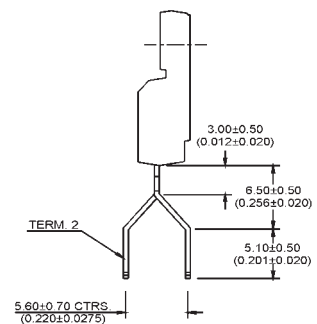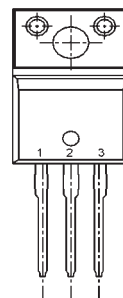


Option - 106

Lead Assignments


- 1 - Gate
- 2 - Drain
- 3 - Source

All dimensions in millimetres (inches)


TO-220 FullPak Leadform Options cont'd

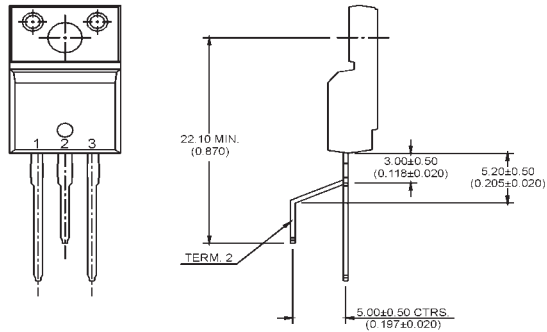


Option - 107

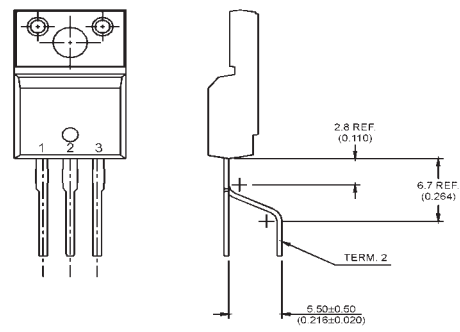


Option - 108

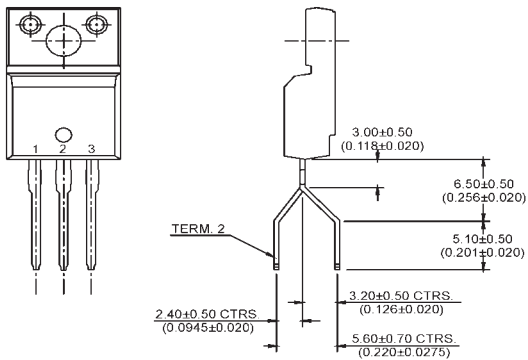


Option - 109

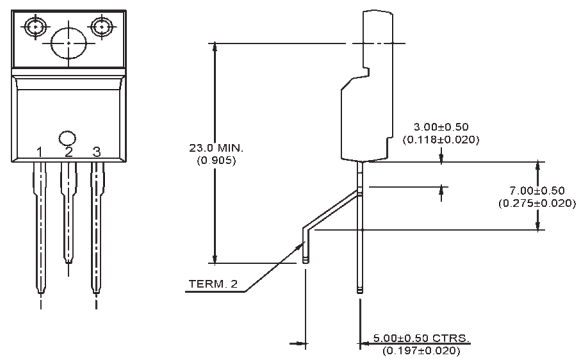

Option - 110

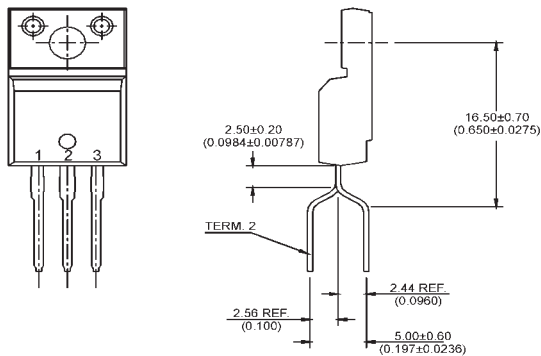

Option - 111

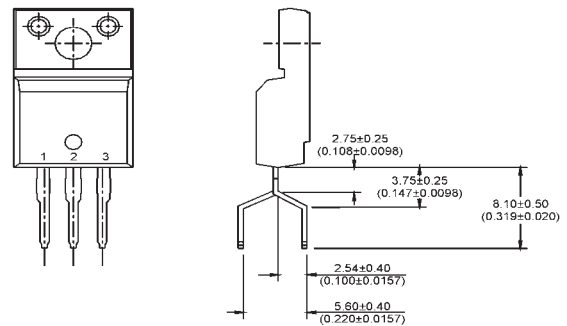



Option - 112

Lead Assignments

- 1 - Gate
- 2 - Drain
- 3 - Source

All dimensions in millimetres (inches)

TO-220 Fullpak Leadform Options cont'd

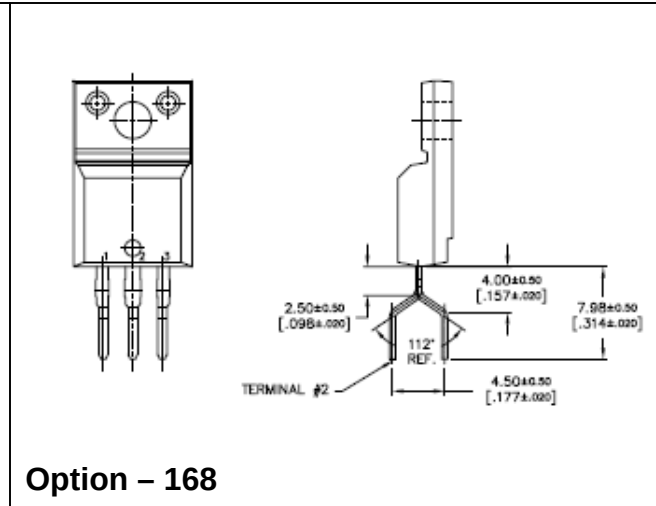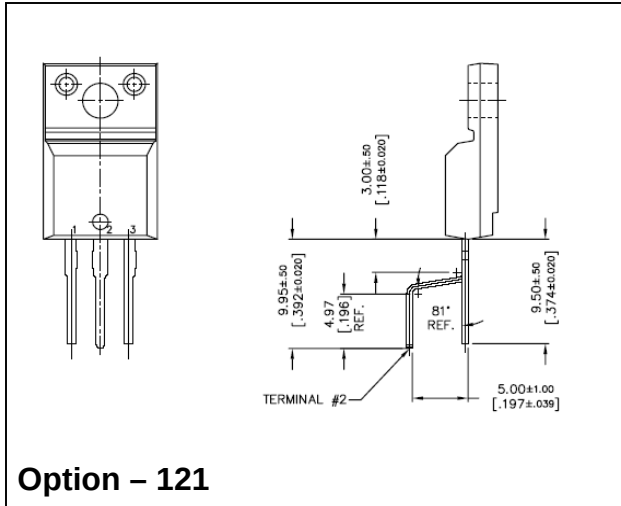

Lead Assignments

- 1- Gate
- 2- Drain
- 3- Source

All dimensions are in millimeters (inches)