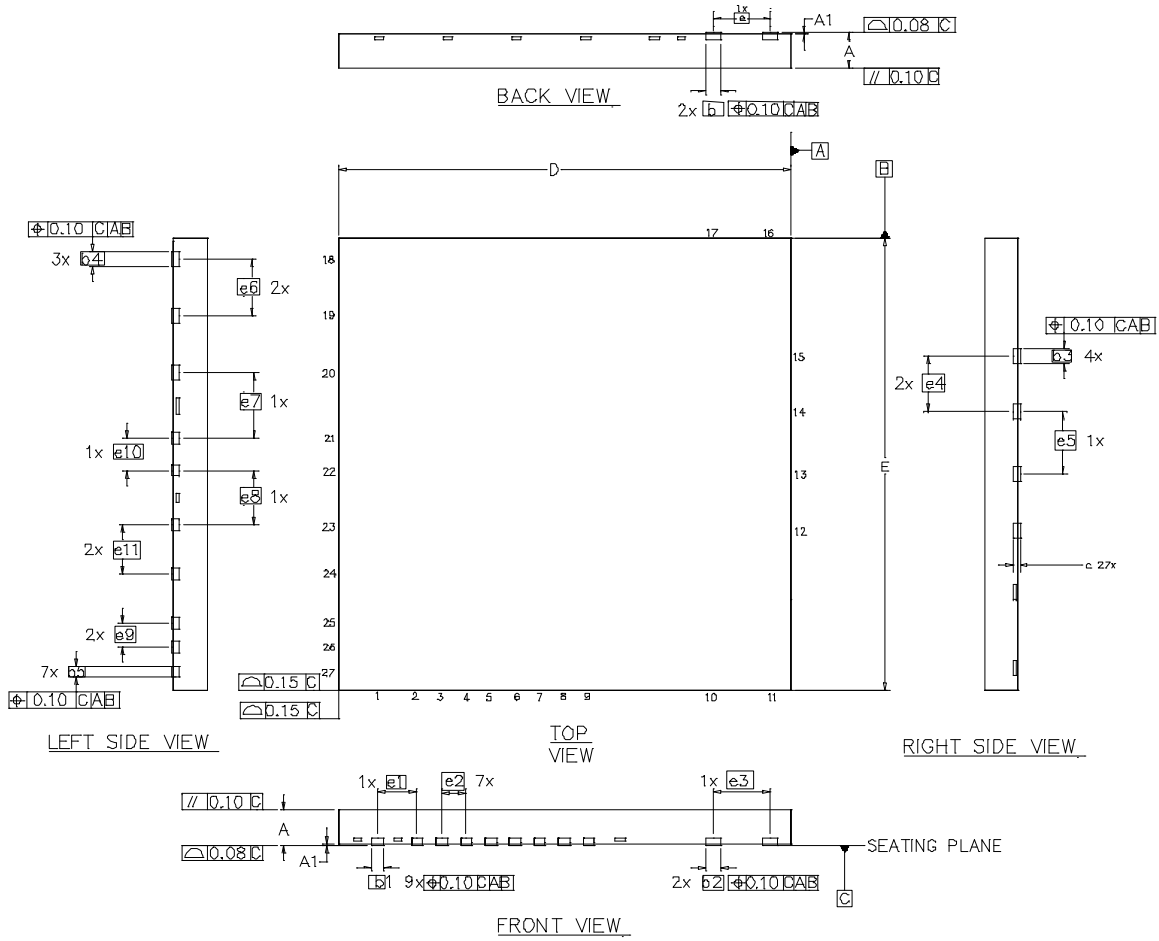


27L Package Outline IRSM836-035MB (Top and Side View)


| DIM | MILLIMETERS | | e | BASIC |
|-----|-------------|-------|-----|-------|
| | MIN | MAX | | |
| A | 0.800 | 1.000 | e1 | 1.056 |
| A1 | 0.000 | 0.050 | e2 | 0.650 |
| b | 0.350 | 0.450 | e3 | 1.500 |
| b1 | 0.250 | 0.350 | e4 | 1.500 |
| b2 | 0.250 | 0.350 | e5 | 1.650 |
| b3 | 0.350 | 0.450 | e6 | 1.500 |
| b4 | 0.350 | 0.450 | e7 | 1.753 |
| b5 | 0.250 | 0.350 | e8 | 1.450 |
| c | 0.203 | REF. | e9 | 0.650 |
| D | 12.000 | BASIC | e10 | 0.866 |
| E | 12.000 | BASIC | e11 | 1.300 |